

Made to Order Common Specifications: -XC24: With Magnetic Shielding Plate -XC25: No Fixed Throttle of Connection Port



30 With Magnetic Shielding Plate -XC24

Symbol

Shields against the magnetic leaked from external slider.

Applicable Series


Series	Description	Model	Action	Vol. no. (for std model)
CY3	Magnetically coupled rodless cylinder	CY3B	Double acting	Web Catalog
REA	Sine rodless cylinder	REA	Double acting	

How to Order

CY3B
REA Standard model no. -XC24
 With magnetic shielding plate ↓

Specifications: Same as standard type

Dimensions

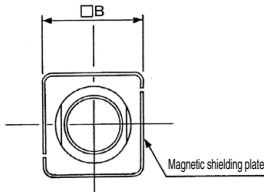

Dimensions	Bore size (mm)								
	ø6	ø10	ø15	ø20	ø25	ø32	ø40	ø50	ø63
□B	19	27	37	38	48	62	72	88	102
Standard external (□B)	17	25	35	36	46	60	70	86	100

* Dimensions except mentioned above are the same as standard type.
* REA is ø25 to ø63.

31 No Fixed Throttle of Connection Port -XC25

Symbol

A CM2 series air cylinder with no restrictor on the rod cover and head cover ports

Applicable Series

Series	Description	Model	Action	Vol. no. (for std model)
CM2	Air cylinder	CM2-Z	Double acting, Single rod	Web Catalog
			Single acting (Spring return/air)	
		CM2W-Z	Double acting, Double rod	
	Non-rotating rod type	CM2K-Z	Double acting, Single rod	
			Double acting, Double rod	
		CM2KW-Z	Single acting (Spring return/air)	
	Direct mount type	CM2R-Z	Double acting, Single rod	
	Non-rotating rod, Direct mount type	CM2RK-Z	Double acting, Single rod	
Smooth cylinder	CM2Y-Z	Double acting, Single rod		

* Except with air cushion (Standard equipment)

How to Order

CM2 Standard model no. -XC25
 No fixed throttle in connection port ↓

Specifications/ Dimensions: Same as standard type

⚠ Caution

1. Use a shock absorber, etc.

When the piston speed exceed 750 mm/s, make sure that direct impact does not apply on the cylinder cover by using an external stopper (shock absorber, etc).